

BUREAU VERITAS
Certification



村田新能源（无锡）有限公司

总部：中国江苏省无锡市新吴区长江路 27 号

统一社会信用代码：91320214722236015U

此份为多场所证书，各分场所见证书附页

必维认证集团认证控股有限公司英国分公司
确证上述单位的管理体系已经评审
并确认符合下列管理体系标准全部适用条款的要求

ISO 14001:2015

体系覆盖范围

总范围：锂离子可充电电池的生产

最初认证周期起始日期：2004 年 6 月 9 日
上一周期的到期日：NA
认证/再认证审核日期：NA
本次认证/再认证周期起始日期：2023 年 2 月 16 日

在证书持有者之管理体系持续符合要求的运行条件下，本证书至下述日期有效：
2026 年 2 月 27 日

证书号：CNBJ314572-U

版本号：No.1， 发证日期：2023 年 2 月 16 日

必维认证集团认证控股有限公司英国分公司
授权代表



0008

认证机构地址：5th Floor, 66 Prescot Street, London E1 8HG, United Kingdom
当地办公室地址：中国上海市黄浦区外马路1288号综合楼四层B室，邮编：200011

需进一步澄清本证书范围和有效状态，以及此管理体系要求的适用性，请电：+86 21 23190329
获证组织必须定期接受监督审核并经审核合格此证书方继续有效。本证书信息可在国家认证认可监督管理委员会官方网站(www.cnca.gov.cn)上查询。

BUREAU VERITAS
Certification



村田新能源（无锡）有限公司

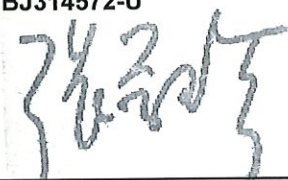
ISO 14001:2015

体系覆盖范围

场所名称	场所地址	场所认证范围
村田新能源（无锡）有限公司	中国江苏省无锡市新吴区长江路 27 号	锂离子可充电电池的生产
村田新能源（无锡）有限公司	中国江苏省无锡市新吴区珠江路 41 号	锂离子可充电电池的生产

证书号: CNBJ314572-U

版本号: No.1, 发证日期: 2023 年 2 月 16 日


必维认证集团认证控股有限公司英国分公司
授权代表



0008

认证机构地址: 5th Floor, 66 Prescot Street, London E1 8HG, United Kingdom
当地办公室地址: 中国上海市黄浦区外马路1288号综合楼四层B室, 邮编: 200011

需进一步澄清本证书范围和有效状态, 以及此管理体系要求的适用性, 请电: +86 21 23190329
获证组织必须定期接受监督审核并经审核合格此证书方继续有效。本证书信息可在国家认证认可监督管理委员会官方网站(www.cnca.gov.cn)上查询。

BUREAU VERITAS
Certification



MURATA ENERGY DEVICE WUXI CO., LTD.

HEAD OFFICE: NO. 27, CHANGJIANG ROAD, XINWU DISTRICT, WUXI CITY, JIANGSU
PROVINCE, P.R.CHINA

Unified social credit code: 91320214722236015U

This is a multi-site certificate, additional site(s) are listed on the next page(s).

*Bureau Veritas Certification Holding SAS - UK Branch certifies that the
Management System of the above organisation has been audited and found to
be in accordance with the requirements of the management system standards
detailed below*

ISO 14001:2015

Scope of certification

OVERALL: PRODUCTION OF LITHIUM-ION RECHARGEABLE BATTERY

Original cycle start date:	9 JUNE 2004
Expiry date of previous cycle:	NA
Certification / Recertification audit date:	NA
Certification / Recertification cycle start date:	16 FEBRUARY 2023

Subject to the continued satisfactory operation of the organisation's Management System,
this certificate expires on: **27 FEBRUARY 2026**

Certificate No.: **CNBJ314572-U**

Version: **No.1**, Issue date: **16 FEBRUARY 2023**


Signed on behalf of BVCH SAS UK Branch



0008

Certification body address: 5th Floor, 66 Prescott Street, London E1 8HG, United Kingdom.

Local office address: Rm. B, F4, No.1288, Waima Road, Huangpu District, Shanghai, China. 200011.

Further clarifications regarding the scope and validity of this certificate, and the applicability of the
management system requirements, please call: +86 21 23190329

Certified organisation has to accept and pass regular surveillance audits, then this certificate can be
continuously valid. Information of this certificate may be obtained by visiting CNCA website
(www.cnca.gov.cn).

BUREAU VERITAS
Certification



MURATA ENERGY DEVICE WUXI CO., LTD.

ISO 14001:2015

Scope of certification

<u>Site Name/Location</u>	<u>Site Address</u>	<u>Site Scope</u>
MURATA ENERGY DEVICE WUXI CO., LTD.	NO. 27, CHANGJIANG ROAD, XINWU DISTRICT, WUXI CITY, JIANGSU PROVINCE, P.R.CHINA	PRODUCTION OF LITHIUM- ION RECHARGEABLE BATTERY
MURATA ENERGY DEVICE WUXI CO., LTD.	NO.41, ZHUJIANG ROAD, XINWU DISTRICT, WUXI CITY, JIANGSU PROVINCE, P.R.CHINA	PRODUCTION OF LITHIUM- ION RECHARGEABLE BATTERY

Certificate No.: **CNBJ314572-U**

Version: **No.1**, Issue date: **16 FEBRUARY 2023**


Signed on behalf of BVCH SAS UK Branch



0008

Certification body address: 5th Floor, 66 Prescott Street, London E1 8HG, United Kingdom.

Local office address: Rm. B, F4, No.1288, Waima Road, Huangpu District, Shanghai, China. 200011.

Further clarifications regarding the scope and validity of this certificate, and the applicability of the management system requirements, please call: +86 21 23190329

Certified organisation has to accept and pass regular surveillance audits, then this certificate can be continuously valid. Information of this certificate may be obtained by visiting CNCA website (www.cnca.gov.cn).